


SELF-LOCKING  
 VIBRATION-RESISTANT  
 INSTALLED WITH STANDARD TOOLS  
 REUSABLE

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM


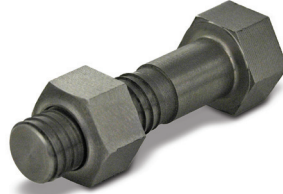


**> MATERIAL:**

416 Stainless Steel, Passivated

Special sizes available upon request.

Sold in pairs

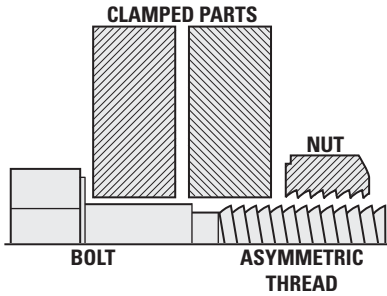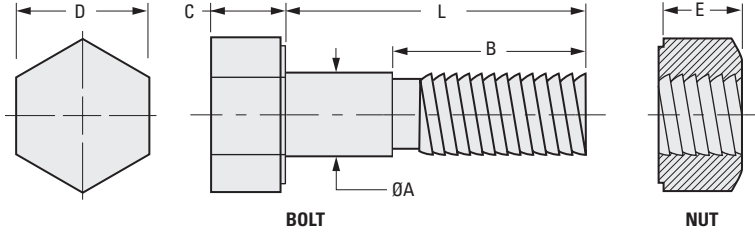

**METRIC COMPONENT**

Catalog Number	A Dia. 0 -0.05	L	B	C	D	E
A 7Z38M0619	6.5	19	19	4	10	6.1
A 7Z38M0625		25				
A 7Z38M0632		32				
A 7Z38M0820	8	20	20	5	14	7
A 7Z38M0825		25				
A 7Z38M0832		32				
A 7Z38M1025	10	25	25	7	16	8.9
A 7Z38M1032		32				
A 7Z38M1038		38				
A 7Z38M1332		32				
A 7Z38M1338	13	38	32	8	18	11.7
A 7Z38M1345		45				




SELF-LOCKING  
 VIBRATION-RESISTANT  
 INSTALLED WITH STANDARD TOOLS  
 REUSABLE

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

**> MATERIAL:**  
 416 Stainless Steel, Passivated

Special sizes available upon request.

Sold in pairs

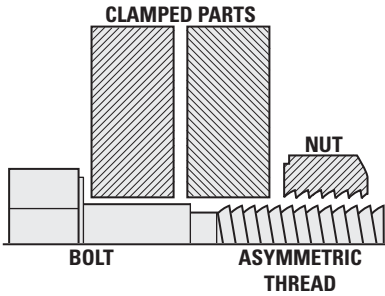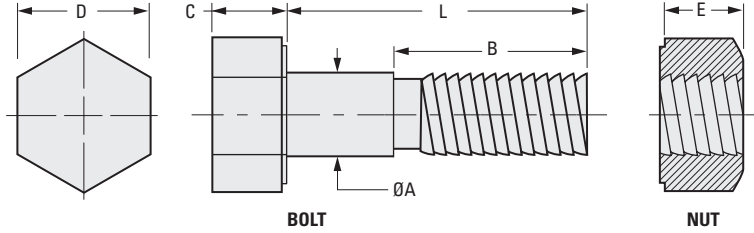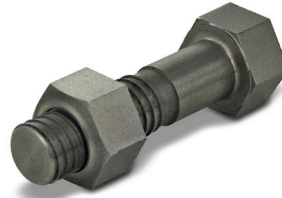

**INCH COMPONENT**

Catalog Number	A Dia. +.000 -.002	L	B	C	D	E
A 7Z38-0812	.2500	.75	.75	.16	.44	.23
A 7Z38-0816		1.00				
A 7Z38-0820		1.25				
A 7Z38-1012	.3125	.75	.75	.20	.50	.27
A 7Z38-1016		1.00				
A 7Z38-1020		1.25				
A 7Z38-1216	.3750	1.00	1.00	.29	.56	.34
A 7Z38-1220		1.25				
A 7Z38-1224		1.50				
A 7Z38-1620	.5000	1.25	1.25	.32	.75	.45
A 7Z38-1624		1.50				
A 7Z38-1628		1.75				