



12 Vdc


Model 1  
5 oz-in  
Rated  
Torque

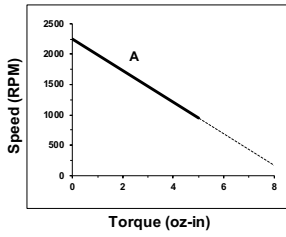


24 Vdc

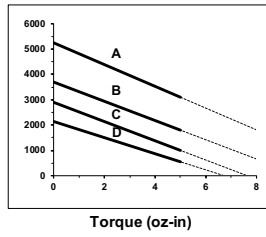


36 Vdc

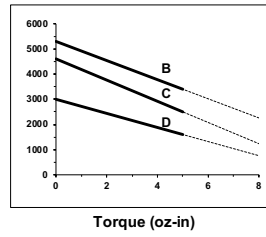






45 Vdc

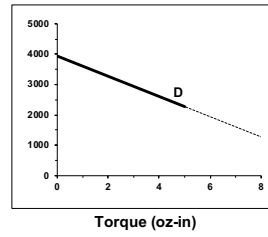






48 Vdc

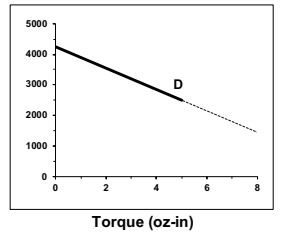






Model 2  
10 oz-in  
Rated  
Torque

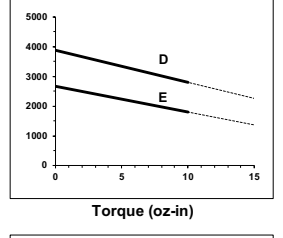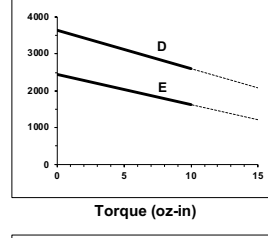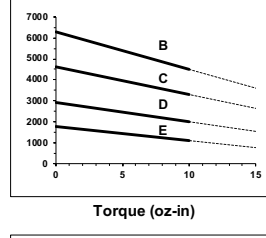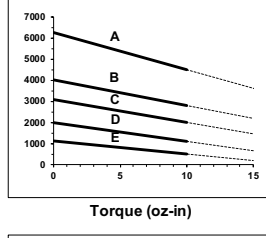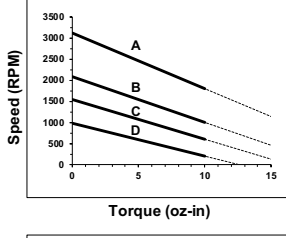

Model 3  
20 oz-in  
Rated  
Torque

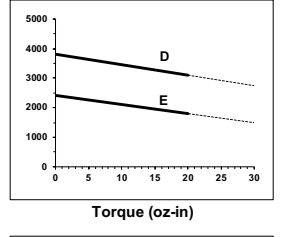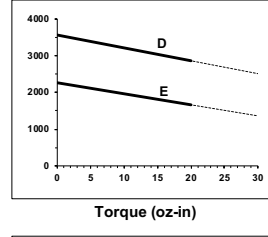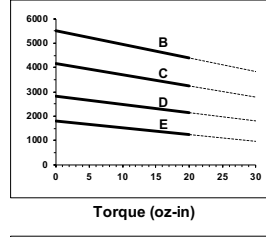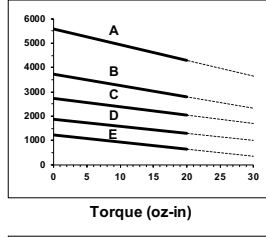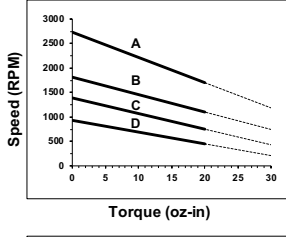

Model 4  
30 oz-in  
Rated  
Torque

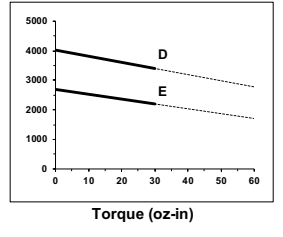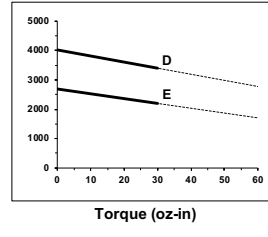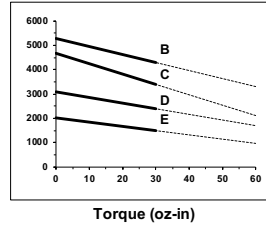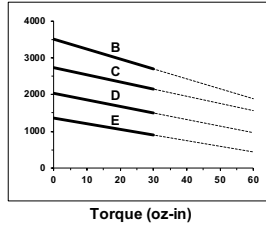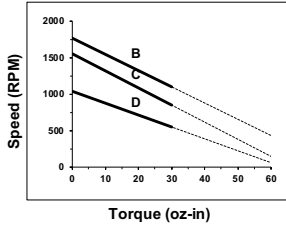

Model 5  
40 oz-in  
Rated  
Torque

